



Disclose and photocopying of this document, exploitation and communication of its contents are not permitted, unless permission is expressly granted. All rights are reserved.

Weitergabe sowie Vervielfältigung dieser Unterlage, Verwertung und Mitteilung ihres Inhalts nicht gestattet, soweit nicht ausdrücklich zugestanden. Alle Rechte vorbehalten.

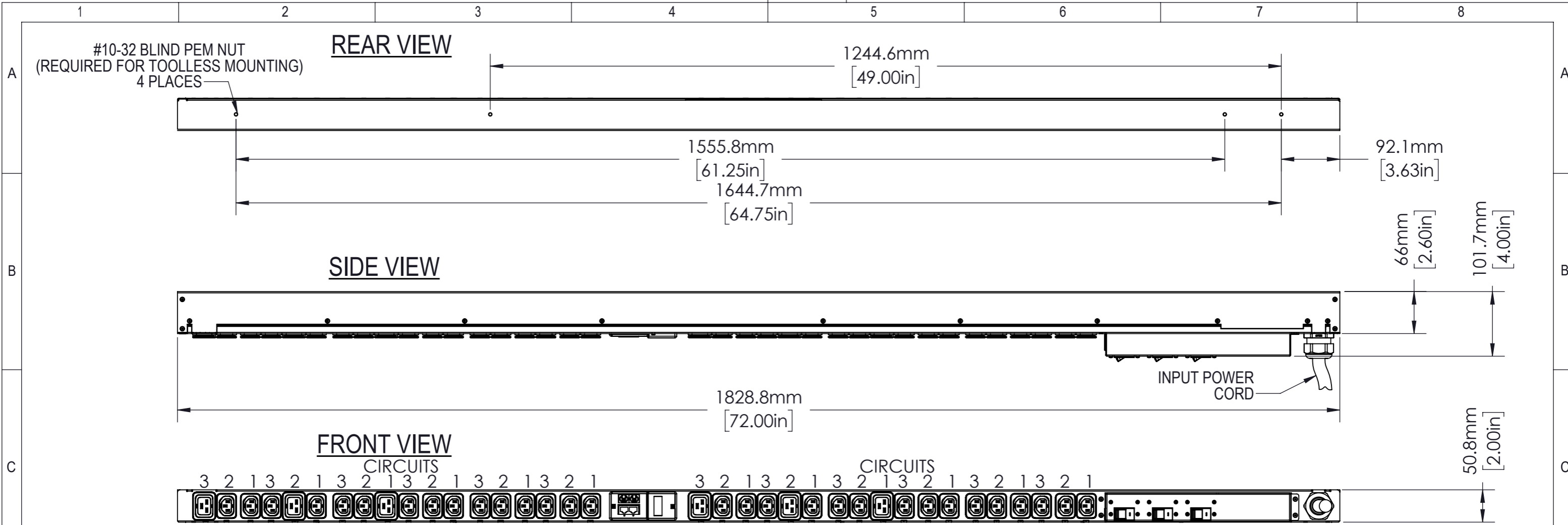

 NEMA L15-30P
(30A, 3/PE, 200-240V)

AGENCY COMPLIANCE:
UL & c-UL Listed 60950
RoHS Compliant
FCC Part 15 Class A Conformance

ENVIRONMENTAL RATING:
Maximum Operating Temperature: 60C / 140F

NOTES
UNIT DIMENSIONS: 72in x 2.0in x 2.6in / 1829mm x 51mm x 66mm
SHIPPED WEIGHT: 22lbs (9.98kg)
SHIPPING DIMENSIONS: 86in x 9in x 7in / 2172mm x 223mm x 159mm
Toolless Mounting Hardware 49in / 1245mm, 61.25in / 1556mm and 64.75in / 1645mm, and
7938 Vertical Mounting Bracket Kit

 
OUTPUT POWER

CIRCUIT	PHASE	RECEPTACLE TYPE	VOLTAGE (V)	MAX. CONTINUOUS AMPS (A)	
				PER RECEPTACLE	PER CIRCUIT
1	A-B	10xC13, 2xC19	200-240	12/16	16
2	B-C	10xC13, 2xC19	200-240	12/16	16
3	C-A	10xC13, 2xC19	200-240	12/16	16

INPUT POWER

INPUT CORD	INPUT PLUG	WIRE COUNT	FREQUENCY (Hz)	VOLTAGE (V)	RATED AMPS (A)	MAX. CONT. AMPS (A)
10 FT	NEMA L15-30P	3/PE	50/60 Hz	200-240V	30	24

METERING PARAMETER	MEASUREMENT ACCURACY
VOLTAGE	±1%
CURRENT	±1% - Input Current
	±2% - Circuit/Breaker Current

	Allgemeintoleranzen General tolerances		Oberfläche Finish	Werkstoff / Material	Gewicht: - Weight:
	-		-	-	-
Drawn			Date	Name	
Checked			22/06/18	SW	
Approved			-	-	
Bezeichnung / Description				-	
Switched, Outlet Level, Vertical, 30A, 208V Delta, (30)U-Lock C13/(6)U-Lock C19				-	
Zeichnungs-Nr. / Drawing no.				-	
VP5665V				-	
Verwendet in / Used in				-	
Maßstab Scale				1:6	
Blatt/Sheet				1/1	
2	ECN 19E0037	06/13/19	JJS	-	
Rev.	Change	Date	Name	-	

