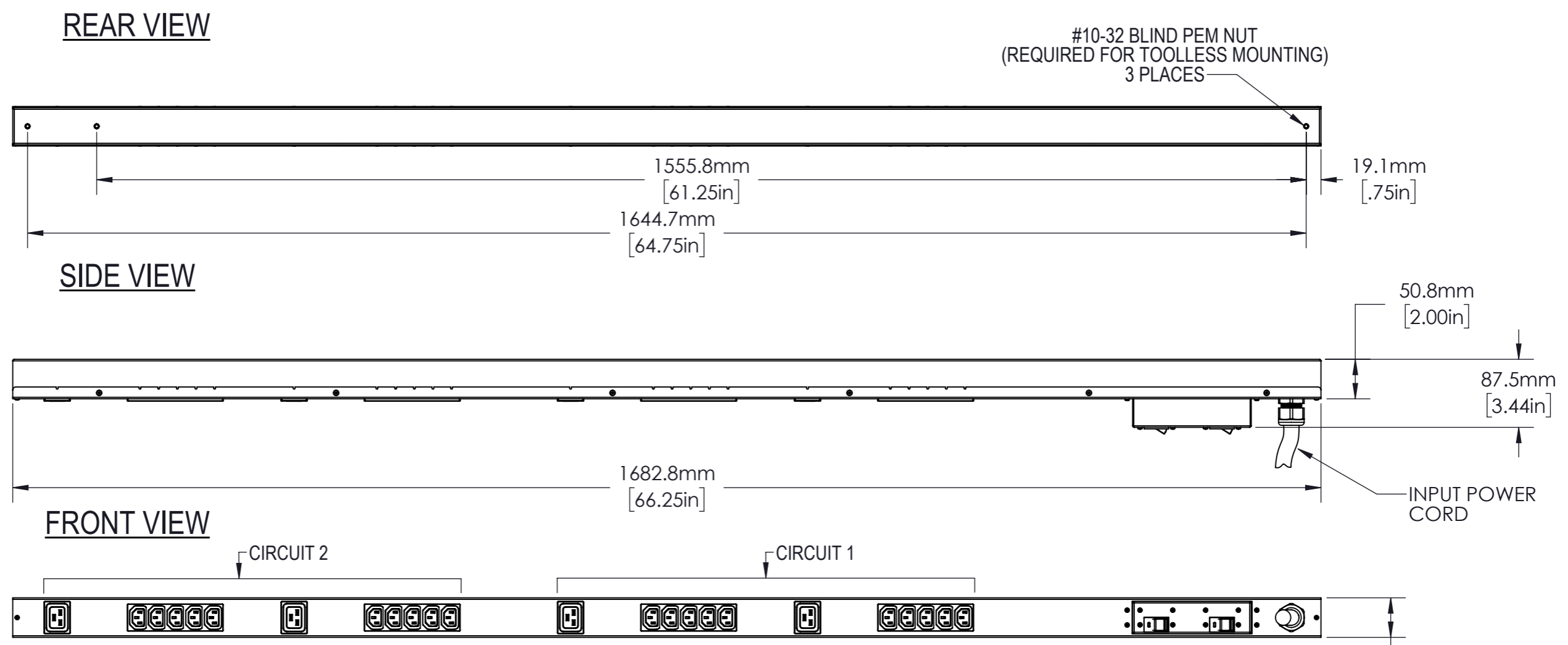


Disclosure and photocopying of this document, exploitation and communication of its contents are not permitted, unless permission is expressly granted. All rights are reserved.

Weitergabe sowie Vervielfältigung dieser Unterlage, Verwertung und Mitteilung ihres Inhalts nicht gestattet, soweit nicht ausdrücklich zugestanden. Alle Rechte vorbehalten.



 NEMA L6-30P
(30 A, 2/PE,
200-240 V)

AGENCY COMPLIANCE:
UL & c-UL Listed 60950
RoHS Compliant
FCC Part 15 Class A Conformance

ENVIRONMENTAL RATING:
Continuous Operating Temperature Range: Full nameplate operation: 10-45C / 50-113F
Continuous Operating Temperature Range: 50% derated operation: 45-60C / 113-140F

 

NOTES
UNIT DIMENSIONS: 66.25in x 2.0in x 2.6in / 1683mm x 51mm x 66mm
SHIPPED WEIGHT: 18lbs (8.16kg)
SHIPPING DIMENSIONS: 72in x 9in x 7in / 1829mm x 223mm x 159mm
Toolless Mounting Hardware 61.25in / 1556mm and 64.75in / 1645mm, and 7938 Vertical Mounting Bracket Kit

OUTPUT POWER

CIRCUIT	PHASE	RECEPTACLE TYPE (QUANTITY)	VOLTAGE (V)	MAX. CONTINUOUS AMPS (A)	
				PER RECEPTACLE	PER CIRCUIT
1	L1-L2	10xC13, 2xC19	200-240	12/16	16
2	L1-L2	10xC13, 2xC19	200-240	12/16	16

INPUT POWER

INPUT CORD	INPUT PLUG	WIRE COUNT	FREQUENCY (Hz)	VOLTAGE (V)	RATED AMPS (A)	MAX. CONT. AMPS (A)
10 FT	NEMAL6-30P	2/PE	50/60 Hz	200-240V	30	24

 Dimensions in mm	Allgemeintoleranzen General tolerances		Oberfläche Finish		Werkstoff / Material		Gewicht: Weight: -
	-		-		-		
	Drawn	13/06/18	Name		Bezeichnung / Description		
	Checked	-	-		Basic, Vertical, 30A, 208V, (20)C13/(4)C19		
Approved	-	-		Zeichnungs-Nr. / Drawing no.			Maßstab Scale
				VP7541			1:6
				Verwendet in / Used in			Blatt/Sheet
				-			1/1
Rev.	Change	Date	Name				
-	-	-	-				