

QUICK CONFIGURE PROGRAM

LIEBERT® EXM™ UPS 10-40 KVA / KW



FEATURES

- 208 Volt, 3-Phase AC input
- Unity communications card with dual simultaneous protocols and environmental sensor support
 - Temperature
 - Humidity
 - Contact Closure
 - Leak
- Internal batteries
- 3-breaker Maintenance Bypass Cabinet (except 10kVA size can be ordered without it)
- Seismic Anchor Kits Available

Power Solution, Quick and Easy:

1. Select capacity (kVA)
2. Select battery runtime
3. Select voltage (30-40 kVA can accommodate 480V with input transformer)
4. Select Startup/Service preference



Liebert EXM UPS
10-40 kVA / kW



Liebert EXM UPS
with 200mm
Maintenance Bypass
Cabinet

The Liebert® EXM™ UPS is now available in Quick Configure SKUs in order to enable rapid quoting and ordering. Simply select the kVA size and battery run time required, and for 30kVA and 40kVA sizes you may also select whether a 480 volt input transformer is required.

Features And Benefits Liebert® EXM™ Ups 10-40 KVA / KW

Ease of Use

- Contractor-friendly design
- Easy front service access
- Intuitive touchscreen control panel
- Remote UPS and battery monitoring options
- LIFE™ and full complement of Liebert Services available


Efficiency

- Market leading UPS efficiency and footprint
- ENERGY STAR® Qualified



Color Touchscreen Control Panel

- Standard on Liebert AC Power products
- Status At A Glance LED light bar indicates warning and alarm condition
- Multiple Access Security Levels
- User-customizable views
- User-friendly graphical interface
- Interactive single-line mimic diagram
- Dedicated warning/alarm and event log
- Dedicated measurements page

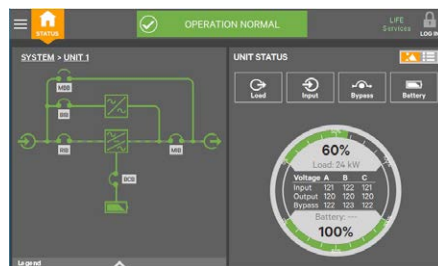

Quick Config and Delivery Option: Fast & Easy

4 DAYS Config to Delivery

Many 10-40kVA models available for delivery within the continental USA

SKU	EXM MODEL NUMBER	DESCRIPTION	LIST PRICE	SUBMITTAL PACKAGE
EXM_10_22_208_208_0	47SA010AACF0008 UNITY-DP / SNMP	10 kva EXM Single Input with 22 minutes of runtime with internal batteries (HX100) Communication Card	\$14,114	10KVA UPS ONLY Packet
UPS_SUP_8x5	-	Start-up 8x5 for 10kva UPS ONLY OPTION	\$1,341	-
UPS_SUP_7x24	-	Start-up 7x24 for 10kva UPS ONLY OPTION	\$1,988	-
EXM_10_22_208_208_3	47SA010AACF0008 47MBA32CCOR1113 UNITY-DP / SNMP	10 kva EXM Single Input with 22 minutes of runtime with internal batteries (HX100) 3 Breaker MBC w/ Key Interlock Right Side Attached Communication Card	\$18,218	10_40KVA UPS_BYPASS
EXM_15_12_208_208_3	47SA015BACF0008 47MBBB32CCOR1232 UNITY-DP / SNMP	15 kva EXM Single Input with 12 minutes of runtime with internal batteries (HX100) 3 Breaker MBC w/ Key Interlock Right Side Attached Communication Card	\$20,901	10_40KVA UPS_BYPASS
EXM_20_13_208_208_3	47SA020CACH0074 47MBC32CCOR1070 UNITY-DP / SNMP	20 kva EXM Single Input with 13 minutes of runtime with internal batteries (HX150) 3 Breaker MBC w/ Key Interlock Right Side Attached Communication Card	\$24,467	10_40KVA UPS_BYPASS
EXM_20_22_208_208_3	47SA020CACM0074 47MBC32CCOR1070 UNITY-DP / SNMP	20 kva EXM Single Input with 22 minutes of runtime with internal batteries (HX205) 3 Breaker MBC w/ Key Interlock Right Side Attached Communication Card	\$24,827	10_40KVA UPS_BYPASS
EXM_30_07_208_208_3	47SA030DACH0339 47MBD32CCOR1454 UNITY-DP / SNMP	30 kva EXM Single Input with 07 minutes of runtime with internal batteries (HX150) 3 Breaker MBC w/ Key Interlock Right Side Attached Communication Card	\$27,149	10_40KVA UPS_BYPASS
EXM_30_13_208_208_3	47SA030DACM0339 47MBD32CCOR1454 UNITY-DP / SNMP	30 kva EXM Single Input with 13 minutes of runtime with internal batteries (HX205) 3 Breaker MBC w/ Key Interlock Right Side Attached Communication Card	\$27,509	10_40KVA UPS_BYPASS
EXM_30_13_480_208_3	47SA030DACM0074 47MBD37ACOR1074 UNITY-DP / SNMP	30 kva EXM Single Input with 13 minutes of runtime with internal batteries (HX205) 3 Breaker MBC w/ 480/208V transformer Key Interlock Right Side Attached Communication Card	\$32,973	30_40KVA UPS_BYPASS DISTRIBUTION
EXM_40_09_208_208_3	47SA040EACM0D99 47MBE32CCOR1946 UNITY-DP / SNMP	40 kva EXM Single Input with 9 minutes of runtime with internal batteries (HX205) 3 Breaker MBC w/ Key Interlock Right Side Attached Communication Card	\$34,480	10_40KVA UPS_BYPASS
EXM_40_09_480_208_3	47SA040EACM0G68 47MBE37ACOR1632 UNITY-DP / SNMP	40 kva EXM Single Input with 9 minutes of runtime with internal batteries (HX205) 3 Breaker MBC w/ 480/208V transformer Key Interlock Right Side Attached Communication Card	\$40,009	30_40KVA UPS_BYPASS DISTRIBUTION
Bundle_SUP_8x5	-	Start-up 8x5 UPS Start-up 8x5 Bypass	\$1,831	-
Bundle_SUP_7x24	-	Start-up 7x24 UPS Start-up 7x24 Bypass	\$2,533	-

Seismic Anchor Kits Available For All Configurations.

VertivCo.com | Vertiv Headquarters, 1050 Dearborn Drive, Columbus, OH, 43085, USA

© 2018 Vertiv Co. All rights reserved. Vertiv and the Vertiv logo are trademarks or registered trademarks of Vertiv Co. All other names and logos referred to are trade names, trademarks or registered trademarks of their respective owners. While every precaution has been taken to ensure accuracy and completeness herein, Vertiv Co. assumes no responsibility, and disclaims all liability, for damages resulting from use of this information or for any errors or omissions. Specifications are subject to change without notice.